

GP2500i

GP SERIES Residential Inverter Portable Generator

Features

- **COsense® Technology** – STOPS, ALERTS, SAVES. Powerful protection against hazardous carbon monoxide.
- **Quiet and Neighbor Friendly** fully enclosed design dramatically reduces noise levels.
- **TruePower™ Technology** provides clean, stable power ideal for sensitive electronics, tools and appliances.
- **Compact and Lightweight** makes transportation easy with built-in handle.
- **Economy Mode** automatically adjusts engine speeds to save fuel and reduce sound emissions.
- **Integrated Off/Run/Choke Knob** simplifies startup procedures.
- **LED Indicators** alert you when unit is low on oil, overloaded, or ready-to-use.
- **USB Port** to charge mobile devices.
- **Parallel Ready** to connect two GP2500i inverter generators or GB Power Stations for twice the power. (Parallel kit sold separately.)
- **Low-oil Level Shutdown** automatically safeguards engine from incurring damage.
- **Covered Outlets** provide added protection from the environment.

Model G0082510 UPC: 696471086256
(50-State/CSA)

Model G0082511 UPC: 696471099942
(50-State)




Model 7118-0 UPC: 696471069303



AC Rated Output Running Watts 2200
AC Maximum Output Starting Watts 2500

Control Panel

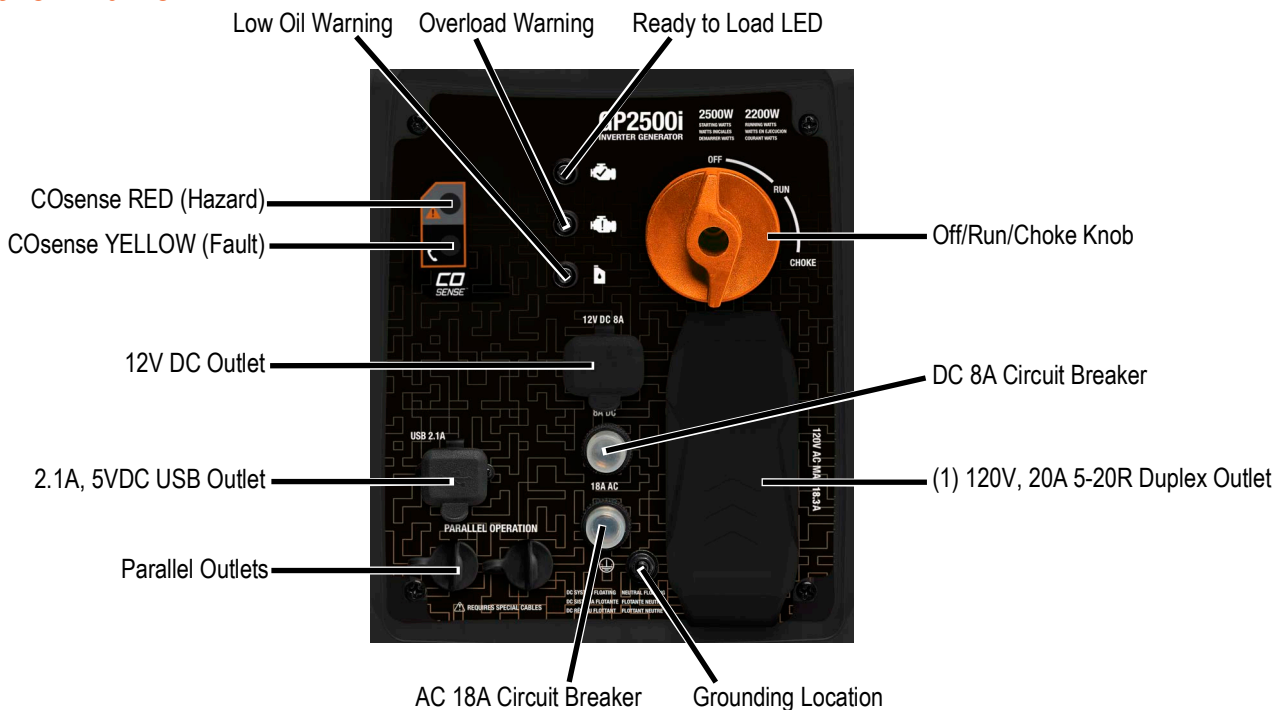

GP2500i

Specifications

Product Series	GP2500i
Model (Configuration)	8251-1 (50-State) 8251-0 (50-State/CSA)
AC Rated Output Running Watts	2200
AC Maximum Output Starting Watts	2500
Rated AC Voltage	120 VAC
Rated AC Frequency	60 Hz
Rated 120 VAC Amperage	18.3
Engine Displacement	98cc
Engine Type	OHV
Engine RPM	Variable
Recommended Oil	10W-30
Oil Capacity Qt (L)	0.36 (0.35)
Lubrication Method	Splash
Choke Location	On Control Panel
Fuel Shut Off	On Control Panel
Starting Method	Recoil Pull Start
Low Oil Shutdown	Low Level
Floating Neutral	Yes

Start Switch Type	Off/Run/Choke Knob
Start Switch Location	On Control Panel
Fuel Tank Capacity Gal (L)	1.0 (3.75)
Run Time at 25% of Rated Load (Hours)	8
Run Time at 50% of Rated Load (Hours)	4.5
Warranty- Residential	3 Year Limited
Warranty- Commercial	1 Year Limited

Product Series	Parallel Kit (sold separately)
Model	7118-0
Receptacle Type	(1) L5-30R Twist Lock (1) TT-30R (RV)
Rated 120 VAC Amperage	28.2 Amp
AC Rated Voltage	120 V
Warranty- Residential	90 Day Limited
Warranty- Commercial	90 Day Limited

Dimensions and Weights

GP2500i	
Length in (mm)	19.7 (500)
Width in (mm)	11.4 (290)
Height in (mm)	17.9 (455)
Carton Length in (mm)	21.7 (550)
Carton Width in (mm)	12.8 (325)
Carton Height in (mm)	19.3 (490)
Unit Weight lbs (kg)	48 (22)
Shipping Weight lbs (kg)	56 (25.6)

Parallel Kit (sold separately)	
Length in (mm)	9.84 (250)
Width in (mm)	4.33 (110)
Height in (mm)	8.27 (210)
Carton Length in (mm)	11.02 (280)
Carton Width in (mm)	9.37 (238)
Carton Height in (mm)	6.10 (155)
Unit Weight lbs (kg)	3.53 (1.6)
Shipping Weight lbs (kg)	3.8 (1.75)

