

XG SERIES

10000 WATT

Portable Generator

GENERAC[®]



Premium, Portable Power for the Home or Job Site

XG SERIES

10000 WATT PORTABLE GENERATOR

The premium XG Series model comes loaded with features that make owning and using a portable generator easy. Comprehensive and accessible controls are user-friendly, and the heavy duty design with full-wrap frame tubing is engineered for years of dependable use.

WHAT'S INCLUDED

- Wheel Kit & Handles
- Engine Oil Supply
- Owner's Manual
- Maintenance Kit

FEATURES AND BENEFITS

EXCLUSIVE LIGHTED POWERBAR™

Displays available power

ILLUMINATED CONTROL PANEL

For improved visibility

FOLD-DOWN, LOCKING HANDLES

Provide easy portability, factory installed

HEAVY-DUTY, NEVER-FLAT, RALLY-STYLE WHEELS

For easy portability

EASY TO READ FUEL GAUGE

Quickly monitor fuel usage

COVERED OUTLETS

Provides added protection from the environment

PLUG-IN BATTERY CHARGE JACK

Keep the battery charged and ready to go

COMPACT DESIGN

Provides unparalleled power to weight ratio




GENERAC OHVI® ENGINE

The power behind the performance.

Features Generac's OHVI engine, which utilizes the same type of pressurized oil lubrication used to give automobile engines long and trouble free lives.

CONTROL PANEL FEATURES

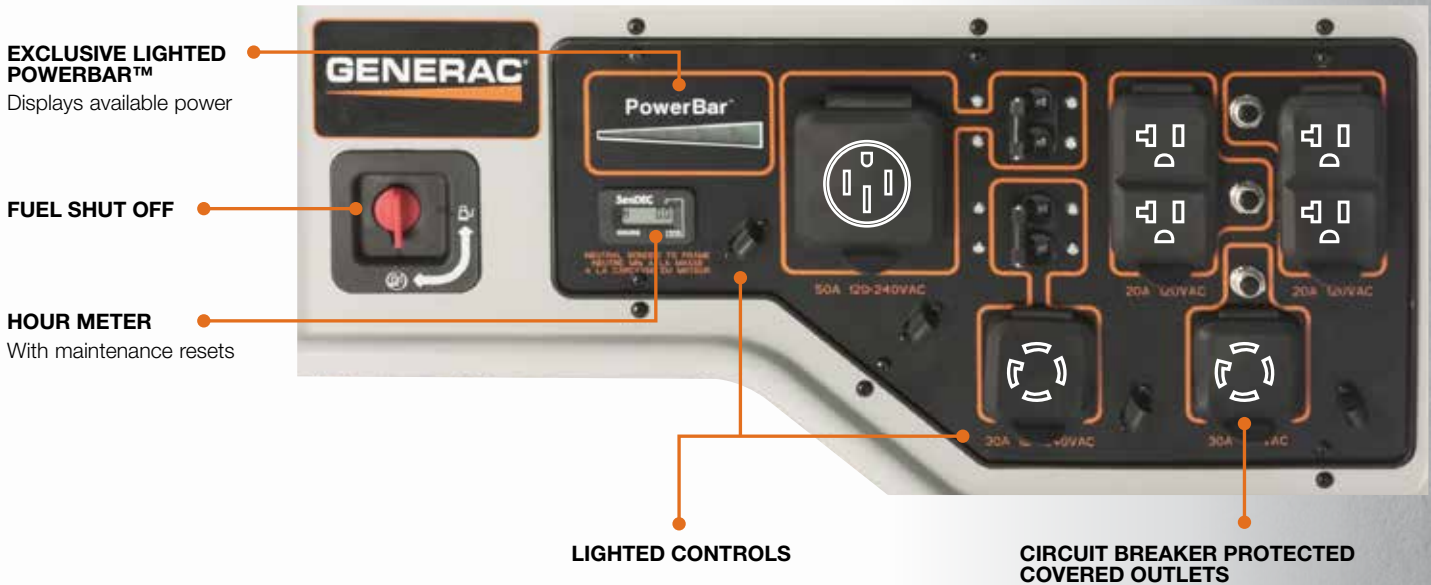

HOW MUCH POWER DO YOU NEED?

Sizing a portable generator is easy. Check out this sample:

- 1 CHOOSE WHICH DEVICES YOU WANT TO POWER AT THE SAME TIME.**
- 2 RECORD AND ADD THE RUNNING WATTS LISTED FOR EACH DEVICE THAT YOU NEED TO POWER.**
- 3 RECORD THE STARTING WATTS LISTED FOR EACH DEVICE.**
- 4 SELECT THE ONE DEVICE WITH THE HIGHEST STARTING WATTS. ADD THAT NUMBER TO THE TOTAL RUNNING WATTS TO DETERMINE THE TOTAL WATTAGE REQUIREMENT.**

DEVICE	RUNNING WATTS	ADDITIONAL STARTING WATTS	GENERATOR SIZE
Paint Sprayer	600	1200	Minimum starting watts for your needs ↓ 9100 Starting watts
Halogen Light	1000	0	
Belt Sander	1200	2400	
Table Saw	1800	4500	
Total	4600	+ 4500 =	

	DEVICE	RUNNING WATTS	ADDITIONAL STARTING WATTS
JOBSITE	Air Compressor - 1 HP	1600	4500
	Air Compressor - 1/2 HP	1000	2000
	Airless Paint Sprayer - 1/3 HP	600	1200
	Belt Sander - 3"	1200	2400
	Bench Grinder - 8"	1400	1100
	Circular Saw - 7-1/4"	1400	2300
	Hand Drill - 1/2"	600	900
	Hand Drill - 3/8"	400	600
	Miter Saw - 10"	1800	1800
	Quartz Halogen Work Light	1000	-
	Reciprocating Saw	960	-
	Table Saw, 10"	2000	2000
	Electric Hedge Trimmer	400	-
	Electric Line Trimmer - 9"	350	-
Electric Chain Saw - 12" (1/2HP)	900	-	
HOUSEHOLD	Computer with a 17" Monitor	800	-
	Microwave - 1000 Watts	1000	-
	Refrigerator/Freezer	700	2200
	Sump Pump 1/2 HP	1050	2150
	Television - 27"	500	-
	Well Pump - 1/2 HP	1000	2100
	Central AC - 24,000 BTU	3800	4950
	Furnace Fan Blower - 1/2 HP	875	2300
	Heat Pump	4700	4500
	Space Heater	1800	-
RECREATION	Window AC - 12,000 BTU	3250	3950
	AM/FM Radio	100	-
	CD / DVD Player	100	-
	Cell Phone Battery Charger	25	-
	Inflator Pump	50	150
	RV Air Conditioner (13,500 BTU)	1500	700

*Watts listed are approximate. Check your appliance for actual requirements. Total wattage requirements assumes intermittent starting of devices.

XG SERIES

PORTABLE GENERATOR



SPECIFICATIONS

SERIES	XG10000E
49-State Model	5802
Running Watts	10000
Starting Watts	12500
Engine Displacement	530cc
Engine Type	Generac OHVI
Pressure Lube w/ Filter	Yes
Starting Method	Electric
Battery Included	Yes
Low Oil Pressure Shutdown	Yes
Fuel Tank in gallons (liters)	10 (37)
Run Time at 50% Load	10 Hours
PowerBar™ Wattage Utilization Meter	Yes
Control Panel LED Lights	Yes
Hour Meter with Maintenance Reset	Yes
Covered Outlets	Yes
Outlets	(2) 120 20A GFCI 5-20R Duplex (1) 120/240V 30A L14-30R Twist Lock (1) 120V 30A L5-30R Twist Lock (1) 125/240V 14-50R
Handle Style	Folding/Locking
Wheel Type	10" Semi-Solid Wheels
Dimensions (L" x W" x H")	30 x 29.5 x 31
Product Weight	300
Warranty - Residential	2 Year Limited
Warranty - Commercial	1 Year Limited