

GP5000

GP SERIES Commercial/Residential Portable Generators

Features


Model 6218-0 UPC: 696471062182 (GOST-R)

- **The Generac OHV engine** incorporates splash lubrication and provides long life.
- **Large-capacity steel fuel tank** with incorporated fuel gauge provides durability and extended run times.
- **Low-oil level shutdown** automatically safeguards engine from damage.
- **Circuit breaker protected outlets.**
- **High leverage fold-down handle** allows easy mobility and storage.
- **Never-flat wheels** for reliable portability.
- **Hardened 1 1/4" steel tube cradle** for added strength and durability.
- **Hour Meter** tracks usage for proper service intervals.



AC Rated Output Running Watts 5000
AC Maximum Output Starting Watts 7000

Control Panel

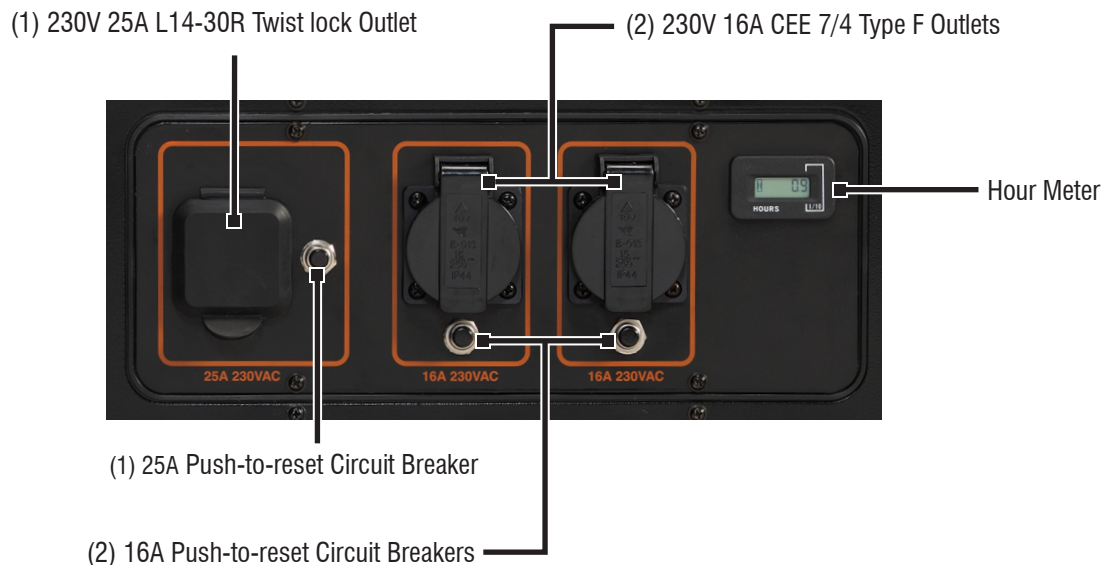

GP5000


specifications

Product Series	GP5000
Model	6218-0
Configuration/Emissions	GOST-R
AC Rated Output Running Watts:	5000
AC Maximum Output Motor Starting Watts:	7000
AC Voltage	230
AC Frequency	50 Hz
Rated VAC Amperage	21.7
Engine Displacement	389cc
Engine Type	OHV
Engine RPM	3000
Recommended Oil	10W-30 / SAE30
Lubrication Method	Splash
Automatic Voltage Regulation (AVR)	Yes
Choke Location	On Engine
Fuel Shut Off	On Fuel Tank
Starting Method	Recoil Pull Start
Low Oil Shutdown Method	Low Level

Start Switch Type	On/Off Switch
Switch Location	On Engine
Fuel Gauge	Built-In Tank
Fuel Tank Capacity Ltrs (Gal)	27 (7.2)
Run Time at 50% (Hours)	10.8
Cord Set	1m Long 30A Twist-lock to 32A 230V Euro Connector
Handle Style	Fold-down locking
Wheel type mm (in)	241.3 (9.5) Solid
Maintenance Kit	Sold Separately
Warranty - Residential	2 Year Ltd
Warranty - Commercial	1 Year Ltd

Dimensions and Weights

Length mm (in)	692 (27.25)
Width mm (in)	687 (27)
Height mm (in)	638 (25)
Extended Length mm (in)	1135 (44.75)
Carton Length mm (in)	802 (31.5)
Carton Width mm (in)	559 (22)
Carton Height mm (in)	614 (24)
Unit Weight kg (lbs)	81 (178.5)
Shipping Weight kg (lbs)	91 (201)

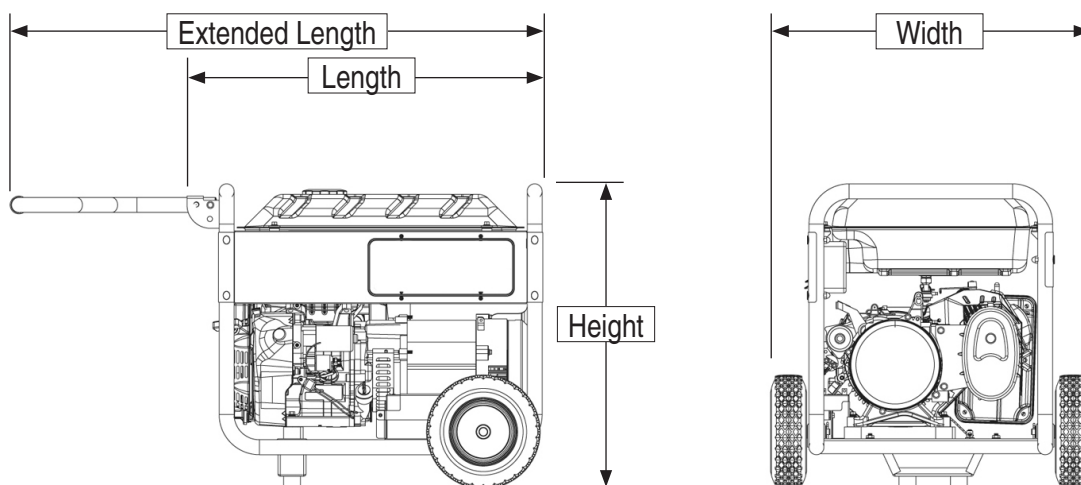

GENERAC[®]

Generac Power Systems, Inc. • P.O. Box 8, Waukesha, WI 53187 • generac.com

©2013 Generac Power Systems, Inc. All rights reserved. All specifications are subject to change without notice. Bulletin 0196320-A / Printed in U.S.A. 09/23/13