

GP3300

GP SERIES Commercial/Residential Portable Generators

Features

- **The Generac OHV engine** with splash lubrication provides a long engine life.
- **Large-capacity steel fuel tank** with incorporated fuel gauge provides durability and extended run times.
- **Low-oil level shutdown** automatically safeguards engine from damage.
- **Hardened steel tube cradle** for added durability and strength.
- **Fold-down handle** for sturdy portability and compact storage.
- **Hour Meter** tracks maintenance intervals.
- **Heavy-duty, never flat wheels** for reliable portability.
- **20A to 30A RV adapter** makes your RV and your generator compatible.

Model 6431-0 UPC: 696471064315 (49ST/Canada)

Model 6432-0 UPC: 696471064322 (California/City of LA)




AC Rated Output Running Watts 3300
AC Maximum Output Starting Watts 3750

49-State Control Panel

(2) 120V 20A 5-20R Duplex Outlets (Model 6431-0 shown)

(2) 120V 20A GFCI 5-20R Duplex Outlets (Model 6432-0)

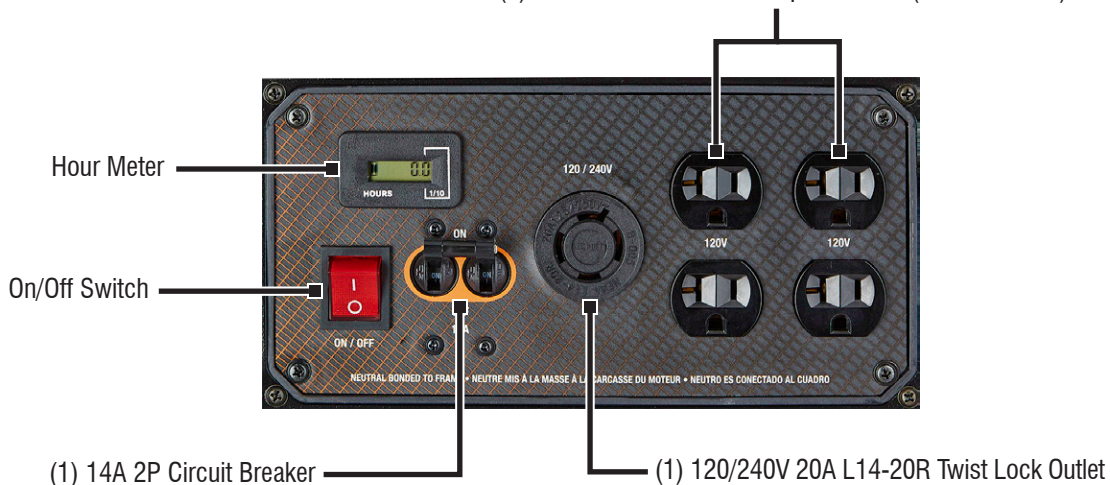

GP3300

specifications

Product Series	GP3300
Model (Configuration)	6431-0 (EPA/CSA) 6432-0 (EPA/CARB/City of LA)
AC Rated Output Running Watts:	3300
AC Maximum Output Motor Starting Watts:	3750
AC Voltage	120/240 VAC
AC Frequency	60 Hz
Rated VAC Amperage	27.5/13.75
Engine Displacement	208cc
Engine Type	OHV
Engine RPM	3600
Recommended Oil	10W-30 / SAE30
Lubrication Method	Splash
Automatic Voltage Regulation	Yes
Choke Location	On Engine
Fuel Shut Off	On Fuel Tank
Starting Method	Recoil Pull Start
Low Oil Shutdown Method	Low Level
Neutral Bonded to Ground	Yes

Start Switch Type	On/Off Switch
Switch Location	On Control Panel
Fuel Gauge	Built-In Tank
Fuel Tank Capacity Gal (Ltr)	3.35 (12.7)
Run Time at 50% (Hours)	10.25
Handle Style	Single Folding
Wheel Type	8" (203 mm) Solid Wheels
Maintenance Kit	Sold Separately
Warranty - Residential	2 Year Ltd
Warranty - Commercial	1 Year Ltd

Dimensions and Weights

Length in (mm)	24.2 (617)
Width in (mm)	22.5 (572)
Height in (mm)	21.0 (533.8)
Extended Length in (mm)	37.0 (939.5)
Carton Length in (mm)	25.2 (640)
Carton Width in (mm)	17.7 (450)
Carton Height in (mm)	19.0 (485)
Unit Weight lbs (kg)	101.5 (46)
Shipping Weight lbs (kg)	106 (48)

