

# Power Grader

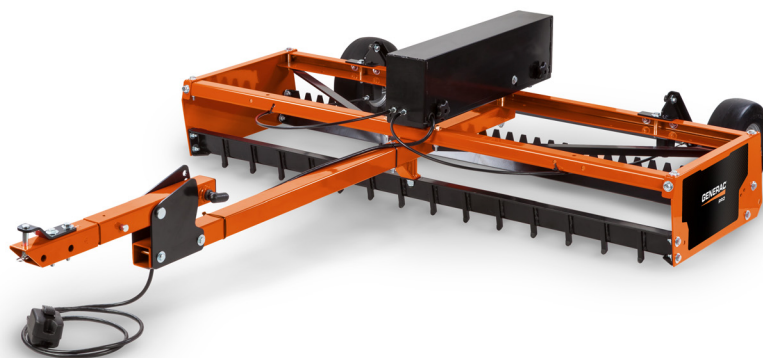
**Commercial**  
Power Tools

**Model:** PG25060XENG  
**UPC:** 843530005790

1 of 2

## GENERAC PRO POWER GRADER

- 60 in (152 cm) grading width.
- Grading depth is adjustable from the tow vehicle using the cabled remote control.
- 14 carbide-tipped grading teeth to loosen hard-packed dirt and gravel.
- Rear leveling blade spreads material evenly.
- Reversible grading board with toothed or flat edge.



## FEATURES

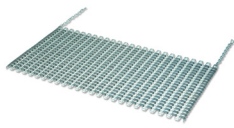

- **Powered, Cabled Remote Control:** Rechargeable battery, powerful electric motor, and precise remote control raise or lower the teeth with the touch of a button.
- **Tungsten Carbide Scarifying Teeth:** Same material used on mining equipment to cut through solid rock.
- **Rechargeable Battery:** Easily removed without tools to bring indoors during the off-season. Charger is included.
- **Easy Hitch:** Comes with both a pin hitch and a ball hitch connector.
- **Powered Actuator:** Powerful actuator provides a 4 in (10.2 cm) stroke, raising the teeth from 4.5 in (11.4 cm) above the surface, to 9/16 in (14.3 mm) below the surface. Steel box housing shields it from the elements and kicked-up debris.

## Specifications

General	
Assembly Required	Yes
Motor	Battery (12V-9AH)
<b>Grading</b>	
Teeth	(14) Carbide-tipped steel
Lowest Teeth Level	9/16 in (14.3 cm) below ground
Highest Teeth Level	4.5 in (11.4 cm)
Actuator	Electric actuator with 4 in (10.2 cm) stroke
Leveling Blade	Solid 0.25 in (6.4 mm) thick steel
Side Rails	Solid 10 gauge steel
<b>Towing</b>	
Towable	Yes
Hitch Type	Pin or ball
Recommended Towing Vehicle	Minimum 14 hp, 400 lbs (181 kg) Lawn/Garden Tractor or 21.9 in <sup>3</sup> (360cc) 4WD ATV/UTV (24 in [61 cm] height) Utility Tractor

Dimensions	
Length	85 in (216 cm)
Width	60 in (152 cm)
Weight	175 lbs (79.4 kg)
Shipping Dimensions	22 in x 61 in x 14.75 in (56 cm x 155 cm x 37.5 cm)
Shipping Weight	222 lbs (100.7 kg)
<b>Material</b>	
Frame	Steel
<b>Wheels/Tires</b>	
Tire Size	11 in (28 cm)
Number of Tires	2
<b>Warranty</b>	
Commercial, Machine	1 year

## Available Accessories

	Model #	Product	Description
	417071	60 in (152.4 cm) Drag Screen	Smooth clumps and imperfections for a truly professional look. The Drag Screen is ideal for finishing sandy driveways, ball fields, riding arenas, and other surfaces that require precise grooming.
	417081	60 in (152.4 cm) Replacement Tooth Bar	The carbide-tipped teeth on the Power Grader are designed to last for many years in normal use. But if the teeth do wear down, they are easy to replace. This will ensure that you will always get the smoothest digging action from your machine.  Tungsten Carbide Scarifying Teeth – This is the same material used on mining equipment to chew through solid rock.