

D6.7L T4F

GENERAC[®]

Diesel Generator

Certified to Lead. Built to Perform.
100 kW | 130 kW | 150 kW | 175 kW

The D6.7L diesel generator delivers dependable standby power in a compact, industrial-grade platform designed for mission-critical applications. Powered by a proven 6.7-liter Iveco/FPT engine and certified for EPA Stationary Emergency use, the D6.7L combines reliable load response, robust construction, and installation flexibility—making it ideal for facilities where uptime, code compliance, and long-term durability matter most.

Ideal Applications

- Healthcare
- Municipal and Government
- Telecommunications
- Edge Computing
- Storage and Distribution
- Manufacturing
- Commercial Buildings



Turbocharged

100 kW, 130 kW, 150 kW, 175 kW

Key Features

Tier 4 Final Certified Power

- Meets the most stringent diesel emissions regulations
- Fully certified (not just compliant) for simplified project approval

Flexible Footprint

- Ideal for space-restricted sites and retrofits
- Streamlined design with optimized airflow and access

Optimized Runtime Support


- 24-hour runtime
- Perfect for long-duration outage protection
 - DEF to Diesel fuel consumption matching

UL2200 3rd Edition Ready

- Certified to the latest UL safety standards
- Designed to meet future regulatory timelines now

Application-Ready Options

- IBP/OSHPD Certified
- Enclosures from Open to Level 2 sound attenuation
- Four certified power nodes under one product platform

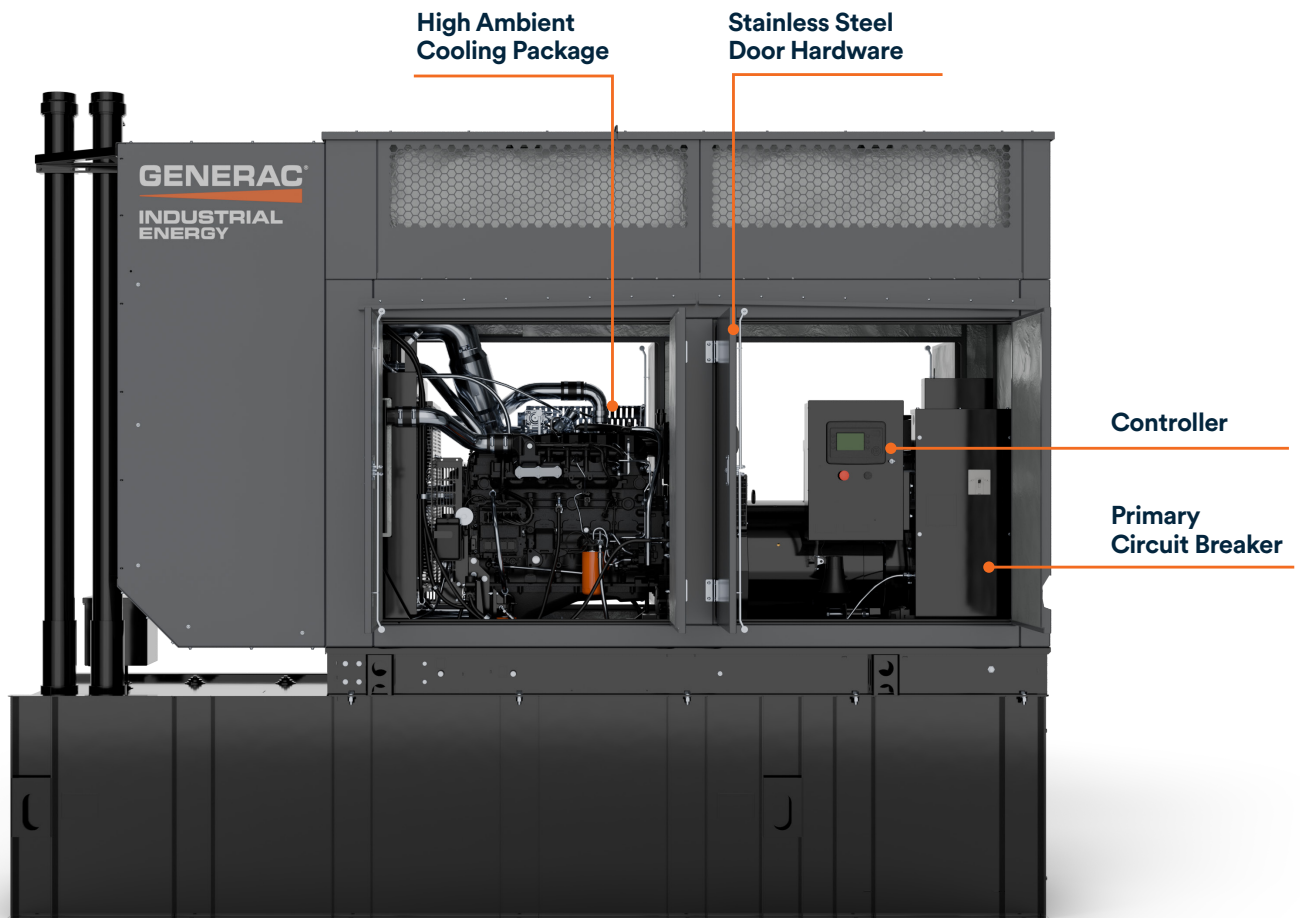


GENERAC®

Generac Power Systems, Inc.
W29290 Hwy 59, Waukesha, WI 53189
1-888-GENERAC (1-888-436-3722)

REV 03/2026

©2026 Generac Power Systems.
All rights reserved. Specifications are
subject to change without notice.

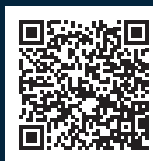

Power your operations
without interruption.
To learn more, visit
[Generac.com](https://www.generac.com).